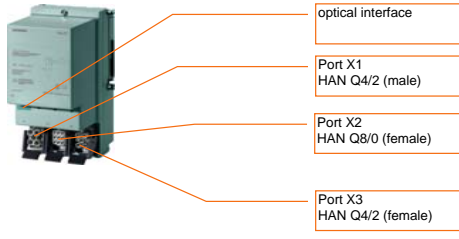
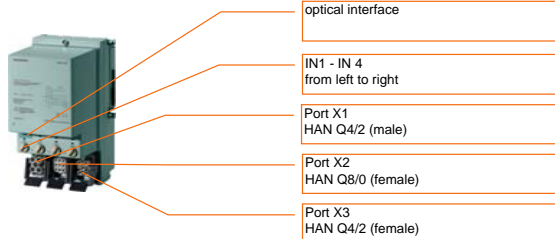
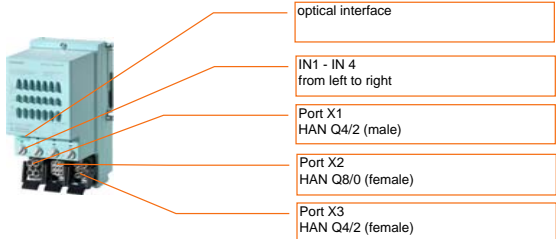


Motor Starter ET 200pro			Motor Starter ET 200pro			Motor Starter ET 200pro		
Motor Starter ET 200pro		Order number	Motor Starter ET 200pro		Order number	Motor Starter ET 200pro		Order number
Motor Starter ET 200pro standard, mechanical		3RK1304*	Motor Starter ET 200pro High Feature, mechanical		3RK1304-5xS40-2AA0 3RK1304-5xS40-2AA3 reversing starter: 3RK1304-5xS40-3AA0 3RK1304-5xS40-3AA3	Motor Starter ET 200pro High Feature, elektrikal		3RK1304-5xS70-2AA0 3RK1304-5xS70-2AA3 reversing starter: 3RK1304-5xS70-3AA0 3RK1304-5xS70-3AA3
Motor Starter ET 200pro High Feature, mechanical			Motor Starter ET 200pro High Feature, electrical					
								
Interfaces		Order number	Interfaces		Order number	Interfaces		Bestellnummer
<b>Port X1 HAN Q4/2 (male)</b>			<b>Port X01 HAN Q4/2 (male)</b>			<b>Port X01 HAN Q4/2 (male)</b>		
<b>Plug</b>			<b>Plug</b>			<b>Plug</b>		
energy connector socket consisting of grommet, angled exit, pin insert	5 contact females / 2,5 mm <sup>2</sup> 2 contact females / 0,5 mm <sup>2</sup>	3RK1911-2BE50 3RK1911-2BE10	energy connector socket consisting of grommet, angled exit, pin insert	5 contact females / 2,5 mm <sup>2</sup> 2 contact females / 0,5 mm <sup>2</sup>	3RK1911-2BE50 3RK1911-2BE10	energy connector socket consisting of grommet, angled exit, pin insert	5 contact females / 2,5 mm <sup>2</sup> 2 contact females / 0,5 mm <sup>2</sup>	3RK1911-2BE50 3RK1911-2BE10
	5 contact females / 4 mm <sup>2</sup> 2 contact females / 0,5 mm <sup>2</sup>	3RK1911-2BE30		5 contact females / 4 mm <sup>2</sup> 2 contact females / 0,5 mm <sup>2</sup>	3RK1911-2BE30		5 contact females / 4 mm <sup>2</sup> 2 contact females / 0,5 mm <sup>2</sup>	3RK1911-2BE30
	5 contact females / 6 mm <sup>2</sup> 2 contact females / 0,5 mm <sup>2</sup>	3RK1922-2BQ00		5 contact females / 6 mm <sup>2</sup> 2 contact females / 0,5 mm <sup>2</sup>	3RK1922-2BQ00		5 contact females / 6 mm <sup>2</sup> 2 contact females / 0,5 mm <sup>2</sup>	3RK1922-2BQ00
energy strapping plug		3RK1922-2BQ00	energy strapping plug		3RK1922-2BQ00	energy strapping plug		3RK1922-2BQ00
<b>one-sided assembled cable</b>			<b>one-sided assembled cable</b>			<b>one-sided assembled cable</b>		
Energy power supply cord, angled, 4 x 4 mm <sup>2</sup>	1,5 m 5,0 m	3RK1911-0DB13 3RK1911-0DB33	Energy power supply cord, angled, 4 x 4 mm <sup>2</sup>	1,5 m 5,0 m	3RK1911-0DB13 3RK1911-0DB33	Energy power supply cord, angled, 4 x 4 mm <sup>2</sup>	1,5 m 5,0 m	3RK1911-0DB13 3RK1911-0DB33
Energy power supply cord, one-sided assembled with „N“ and stud Pin 11 and 12 for plug monitoring, with HAN Q4/2, angled; one-sided open; 5 x 4 mm <sup>2</sup>	1,5 m 5,0 m	3RK1 911-0DC13 3RK1 911-0DC33	Energy power supply cord, one-sided assembled with „N“ and stud Pin 11 and 12 for plug monitoring, with HAN Q4/2, angled; one-sided open; 5 x 4 mm <sup>2</sup>	1,5 m 5,0 m	3RK1 911-0DC13 3RK1 911-0DC33	Energy power supply cord, one-sided assembled with „N“ and stud Pin 11 and 12 for plug monitoring, with HAN Q4/2, angled; one-sided open; 5 x 4 mm <sup>2</sup>	1,5 m 5,0 m	3RK1 911-0DC13 3RK1 911-0DC33
end cap for energy bus	(10 units) (1 unit)	3RK1902-0CJ00 3RK1902-0CK00	end cap for energy bus	(10 units) (1 unit)	3RK1902-0CJ00 3RK1902-0CK00	end cap for energy bus	(10 units) (1 unit)	3RK1902-0CJ00 3RK1902-0CK00
<b>Port X02 HAN Q8/0 (female)</b>			<b>Port X02 HAN Q8/0 (female)</b>			<b>Port X02 HAN Q8/0 (female)</b>		
<b>Plug</b>			<b>Plug</b>			<b>Plug</b>		
Motor connector socket consisting of grommet, angled exit, inclusive screw joints	8 contact males / 1,5 mm <sup>2</sup> 6 contact males / 2,5 mm <sup>2</sup>	3RK1902-0CE00 3RK1902-0CC00	Motor connector socket consisting of grommet, angled exit, inclusive screw joints	8 contact males / 1,5 mm <sup>2</sup> 6 contact males / 2,5 mm <sup>2</sup>	3RK1902-0CE00 3RK1902-0CC00	Motor connector socket consisting of grommet, angled exit, inclusive screw joints	8 contact males / 1,5 mm <sup>2</sup> 6 contact males / 2,5 mm <sup>2</sup>	3RK1902-0CE00 3RK1902-0CC00
<b>one-sided assembled cable</b>			<b>one-sided assembled cable</b>			<b>one-sided assembled cable</b>		
Motor cable, angled, length 5 m	Motor cable for motor without brake, 4 x 1,5 mm <sup>2</sup> Motor cable for motor with brake, 6 x 1,5 mm <sup>2</sup>	3RK1911-0EB31 3RK1911-0ED31	Motor cable, angled, length 5 m	Motor cable for motor without brake, 4 x 1,5 mm <sup>2</sup> Motor cable for motor with brake, 6 x 1,5 mm <sup>2</sup>	3RK1911-0EB31 3RK1911-0ED31	Motor cable, angled, length 5 m	Motor cable for motor without brake, 4 x 1,5 mm <sup>2</sup> Motor cable for motor with brake, 6 x 1,5 mm <sup>2</sup>	3RK1911-0EB31 3RK1911-0ED31
end cap for energy bus	(10 units) (1 unit)	3RK1902-0CJ00 3RK1902-0CK00	end cap for energy bus	(10 units) (1 unit)	3RK1902-0CJ00 3RK1902-0CK00	end cap for energy bus	(10 units) (1 unit)	3RK1902-0CJ00 3RK1902-0CK00
<b>Port X03 HAN Q4/2 (female)</b>			<b>Port X03 HAN Q4/2 (female)</b>			<b>Port X03 HAN Q4/2 (female)</b>		
<b>Plug</b>			<b>Plug</b>			<b>Plug</b>		
energy strapping plug		3RK1922-2BQ00	energy strapping plug		3RK1922-2BQ00	energy strapping plug		3RK1922-2BQ00
energy forwarding plug consisting of grommet, angled exit, inclusive screw joints	4 contact males / 2,5 mm <sup>2</sup> 4 contact males / 4 mm <sup>2</sup>	3RK1911-2BF50 3RK1911-2BF10	energy forwarding plug consisting of grommet, angled exit, inclusive screw joints	4 contact males / 2,5 mm <sup>2</sup> 4 contact males / 4 mm <sup>2</sup>	3RK1911-2BF50 3RK1911-2BF10	energy forwarding plug consisting of grommet, angled exit, inclusive screw joints	4 contact males / 2,5 mm <sup>2</sup> 4 contact males / 4 mm <sup>2</sup>	3RK1911-2BF50 3RK1911-2BF10
end cap for energy bus	(10 units) (1 unit)	3RK1902-0CJ00 3RK1902-0CK00	end cap for energy bus	(10 units) (1 unit)	3RK1902-0CJ00 3RK1902-0CK00	end cap for energy bus	(10 units) (1 unit)	3RK1902-0CJ00 3RK1902-0CK00
<b>optical interface</b>			<b>M12 socket (IN1-IN4)</b>			<b>M12 socket (IN1-IN4)</b>		
PC cable with RS232		3RK1922-2BP00	<b>non-assembled plug</b>			<b>non-assembled plug</b>		
USB interface cable, 2,5 m		6SL3555-0PA00-2AA0	M12 plug, 5-pin, max. 0,75 mm <sup>2</sup> , spring clips		3RK1902-4BA00-5AA0	M12 plug, 5-pin, max. 0,75 mm <sup>2</sup> , spring clips		3RK1902-4BA00-5AA0
<b>at motor (not in draft version)</b>			<b>assembled cables</b>			<b>assembled cables</b>		
motor plug consisting of grommet, straight exit, inclusive star point link	7 contact males / 1,5 mm <sup>2</sup> 7 contact males / 2,5 mm <sup>2</sup>	3RK1911-2BM21 3RK1911-2BM22	M12 plug line (PUR jacket), assembled double-sided with female and male, 4 x 0,34 mm <sup>2</sup>	1,5 m	3RK1902-4PB15-3AA0	M12 plug line (PUR jacket), assembled double-sided with female and male, 4 x 0,34 mm <sup>2</sup>	1,5 m	3RK1902-4PB15-3AA0
			end cap for not used M12-ports		3RX9802-0AA00	end cap for not used M12-ports		3RX9802-0AA00
motor plug with EMV-protective electric wiring consisting of grommet, straight exit, inclusive star point link, inclusive screw joints	7 contact males / 1,5 mm <sup>2</sup> 7 contact males / 2,5 mm <sup>2</sup>	3RK1911-2BL21 3RK1911-2BL22	<b>optical interface</b>			<b>optical interface</b>		
			PC cable with RS232		3RK1922-2BP00	PC cable with RS232		3RK1922-2BP00
			USB interface cable, 2,5 m		6SL3555-0PA00-2AA0	USB interface cable, 2,5 m		6SL3555-0PA00-2AA0
<b>at motor (not in draft version)</b>			<b>at motor (not in draft version)</b>			<b>at motor (not in draft version)</b>		
motor plug consisting of grommet, straight exit, inclusive star point link	7 contact males / 1,5 mm <sup>2</sup> 7 contact males / 2,5 mm <sup>2</sup>	3RK1911-2BM21 3RK1911-2BM22	motor plug consisting of grommet, straight exit, inclusive star point link	7 contact males / 1,5 mm <sup>2</sup> 7 contact males / 2,5 mm <sup>2</sup>	3RK1911-2BM21 3RK1911-2BM22	motor plug consisting of grommet, straight exit, inclusive star point link	7 contact males / 1,5 mm <sup>2</sup> 7 contact males / 2,5 mm <sup>2</sup>	3RK1911-2BM21 3RK1911-2BM22

			motor plug with EMV-protective electric wiring consisting of grommet, straight exit, inclusive star point link, inclusive screw joints	7 contact males / 1,5 mm <sup>2</sup> 7 contact males / 2,5 mm <sup>2</sup>	3RK1911-2BL21 3RK1911-2BL22	motor plug with EMV-protective electric wiring consisting of grommet, straight exit, inclusive star point link, inclusive screw joints	7 contact males / 1,5 mm <sup>2</sup> 7 contact males / 2,5 mm <sup>2</sup>	3RK1911-2BL21 3RK1911-2BL22
--	--	--	--	--	--------------------------------	--	--	--------------------------------