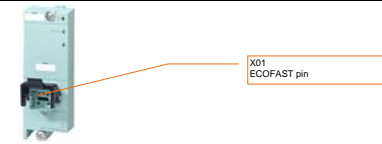
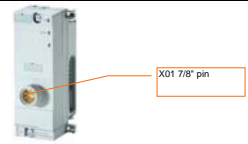
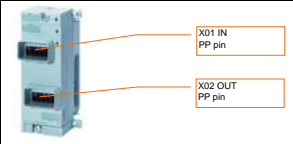
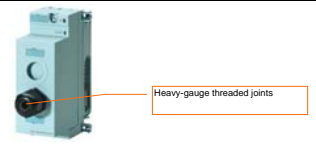


**Power module PM-E**

Power module	Order number	Connection module	Order number	Connection module	Order number	Connection module	Order number
PM-E DC 24V	6ES7148-4CA00-0AA0	CM PM ECOFAST	6ES7194-4BA00-0AA0	CM PM 7/8"	6ES7194-4BD00-0AA0	CM PM PP	6ES7194-4BE00-0AA0
							
<b>Interfaces</b>	<b>Order number</b>	<b>Interfaces</b>	<b>Order number</b>	<b>Interfaces</b>	<b>Order number</b>	<b>Interfaces</b>	<b>Order number</b>
<b>X01 ECOFAST (pin)</b>		<b>X01 7/8" (pin)</b>		<b>X01 IN PP (pin)</b>		<b>Heavy-gauge threaded joints</b>	
<b>non-assembled connectors</b>		<b>non-assembled connectors</b>		<b>non-assembled connectors</b>		<b>non-assembled cables</b>	
PROFIBUS ECOFAST Hybrid Plug 180 with socket insert	6GK1905-0CB00	7/8" connector 180 with socket insert	6GK1905-0FB00	Push-pull connection plug for 1L+/2L+ with socket insert	6GK1907-0AB10-6AA0	Energy Cable, triable, 5 x 1.5 mm <sup>2</sup>	6XV1830-8AH10
PROFIBUS ECOFAST Hybrid Plug angled with socket insert	6GK1905-0CD00	7/8" connector angled with socket insert	3RK1902-3DA00	<b>pre-assembled cables</b>			
<b>non-assembled cables</b>		<b>non-assembled cables</b>		Push-pull connecting cable for 1L+/2L+, pre-assembled at both ends with socket insert	(on request)		
PROFIBUS ECOFAST Hybrid Cable, trailing cable (PUR sheath)	20m 6XV1830-7AN20	Energy Cable, triable, 5 x 1.5 mm <sup>2</sup>	6XV1830-8AH10	<b>X02 OUT PP (pin)</b>			
	50m 6XV1830-7AN50	<b>pre-assembled cable</b>		<b>non-assembled connectors</b>			
PROFIBUS ECOFAST Hybrid Cable, trailing cable (PUR sheath); lask by the meter	6XV1830-7AH10	7/8" connecting cable for supplying triable energy cable, 5 x 1.5 mm <sup>2</sup> , pre-assembled at both ends with 7/8" connectors 180 (one end socket, one end pin)	0.3m 6XV1822-5BE30	Push-pull connection plug for 1L+/2L+ with socket insert	6GK1907-0AB10-6AA0		
PROFIBUS ECOFAST Hybrid Cable GP, trailing cable (PVC sheath)	20m 6XV1860-4PN20		0.5m 6XV1822-5BE50	<b>pre-assembled cables</b>			
	50m 6XV1860-4PN50		1.0m 6XV1822-5BH10	Push-pull connecting cable for 1L+/2L+, pre-assembled at both ends with socket insert	(on request)		
	100m 6XV1860-4PT10		1.5 m 6XV1822-5BH15	Push-pull cover caps	6ES7194-4JA50-0AA0		
<b>pre-assembled cables</b>			2.0 m 6XV1822-5BH20				
PROFIBUS ECOFAST Hybrid Cable, triable (PUR sheath), pre-assembled at both ends with ECOFAST Hybrid Plug 180	1.5 m 6XV1830-7BH15		3.0 m 6XV1822-5BH30				
	3.0 m 6XV1830-7BH30		5.0 m 6XV1822-5BH50				
	5.0 m 6XV1830-7BH50		10.0 m 6XV1822-5BN10				
	10.0 m 6XV1830-7BN10		15.0 m 6XV1822-5BN15				
	15.0 m 6XV1830-7BH15	7/8" connecting cable for supplying triable energy cable, 5 x 1.5 mm <sup>2</sup> , pre-assembled at both ends with 7/8" connectors angled (one end socket, one end pin)	11.5 m 6XV1822-5BH15-0SB0 <sup>1)</sup>				
	20.0 m 6XV1830-7BN20		2.0 m 6XV1822-5BH20-0SB0 <sup>1)</sup>				
	25.0 m 6XV1830-7BN25		3.0 m 3RK1902-3NB30				
	30.0 m 6XV1830-7BN30		5.0 m 3RK1902-3NB50				
	35.0 m 6XV1830-7BN35		10.0 m 3RK1902-3NC10				
	40.0 m 6XV1830-7BN40		15.0 m 6XV1822-5BN15-0SB0 <sup>1)</sup>				
	45.0 m 6XV1830-7BN45	7/8" connecting cable for supplying triable energy cable, 5 x 1.5 mm <sup>2</sup> , pre-assembled at one end with 7/8" connector angled (one end socket, one end open cable)	3.0 m 3RK1902-3GB30				
	50.0 m 6XV1830-7BN50		5.0 m 3RK1902-3GB50				
PROFIBUS ECOFAST Hybrid Cable GP, triable (PVC sheath), pre-assembled at both ends with ECOFAST Hybrid Plug 180	1.5 m 6XV1860-3PH15		10.0 m 3RK1902-3GC10				
	3.0 m 6XV1860-3PH30						
	5.0 m 6XV1860-3PH50						
	10.0 m 6XV1860-3PN10						
	15.0 m 6XV1860-3PN15						
	20.0 m 6XV1860-3PN20						
	25.0 m 6XV1860-3PN25						
	30.0 m 6XV1860-3PN30						
	35.0 m 6XV1860-3PN35						
	40.0 m 6XV1860-3PN40						
	45.0 m 6XV1860-3PN45						
	50.0 m 6XV1860-3PN50						

<sup>1)</sup> Ordering with ORG-ID: 10001539