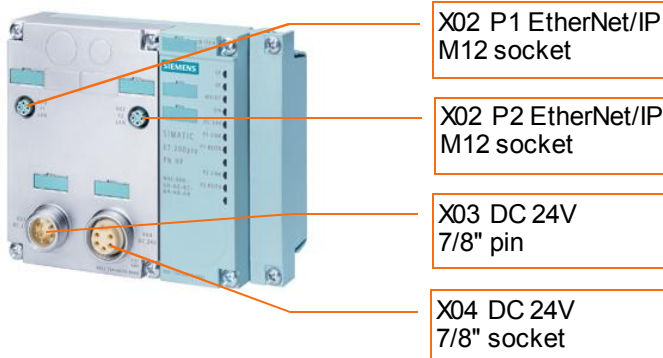


Interface modules EtherNet/IP		
Interface modules		
EtherNet/IP Interface module		Article number ZNX: EIP200PRO
Connection modules		
CM IM M12, 7/8"		Article number ZNX: ET200PROCM1
		
Interfaces		
X02 P1 EtherNet/IP (M12 socket)		
Non-assembled connectors		
PROFINET M12 connector d-coded with FastConnect connecting method, 180°		
- 1 piece per pack		6GK1901-0DB20-6AA0
- 8 pieces per pack		6GK1901-0DB20-6AA8
PROFINET M12-Steckverbinder d-kodiert with short assembly times due to their insulation-displacement technology method, 180°		
- 1 piece per pack		6GK1901-0DB10-6AA0
- 8 pieces per pack		6GK1901-0DB10-6AA8
PROFINET M12 connector d-coded, angled		3RK1902-2DA00
Non-assembled cables		
PROFINET FC cable		
- FC TP Standard Cable		6XV1840-2AH10
- FC TP Trailing Cable		6XV1840-3AH10
- FC TP Trailing Cable GP		6XV1870-2D
- FC TP Marine Cable		6XV1840-4AH10
- FC TP Torsion Cable		6XV1870-2F
- FC TP Flexible Cable GP		6XV1870-2B
- FC TP FRNC Cable		6XV1871-2F
- FC TP Food Cable		6XV1871-2L
- FC TP Festoon Cable GP		6XV1871-2S

Pre-assembled cables		
PROFINET M12 trailable connecting cable, pre-assembled at both ends with M12 connectors, 180° (pin)	0,3 m	6XV1870-8AE30
	5,0 m	6XV1870-8AE50
	1,0 m	6XV1870-8AH10
	1,5 m	6XV1870-8AH15
	2,0 m	6XV1870-8AH20
	3,0 m	6XV1870-8AH30
	5,0 m	6XV1870-8AH50
	10,0 m	6XV1870-8AN10
	15,0 m	6XV1870-8AN15
PROFINET M12 trailable connecting cable, pre-assembled at both ends with M12 connectors, angled (pin)	0,3 m	6XV1870-8GE30
	5,0 m	6XV1870-8GE50
	1,0 m	6XV1870-8GH10
	1,5 m	6XV1870-8GH15
	2,0 m	6XV1870-8GH20
	3,0 m	6XV1870-8GH30
	5,0 m	6XV1870-8GH50
	10,0 m	6XV1870-8GN10
	15,0 m	6XV1870-8GN15
PROFINET M12 trailable connecting cable, pre-assembled at one end with M12 connector, angled (pin), other end open cable	3,0 m	3RK1902-2HB30
	5,0 m	3RK1902-2HB50
	10,0 m	3RK1902-2HC10
PROFINET M12 trailable connecting cable, pre-assembled at one end with M12 connector 180° (pin), other end with RJ45 Plug 145°	2,0 m	6XV1871-5TH20
	3,0 m	6XV1871-5TH30
	5,0 m	6XV1871-5TH50
	10,0 m	6XV1871-5TN10
	15,0 m	6XV1871-5TN15
M12 cover caps		3RX9802-0AA00
X02 P2 EtherNet/IP (M12 socket)		
Non-assembled connectors		
PROFINET M12 connector d-coded with FastConnect connecting method, 180°		
- 1 piece per pack		6GK1901-0DB20-6AA0
- 8 pieces per pack		6GK1901-0DB20-6AA8
PROFINET M12-Steckverbinder d-kodiert with short assembly times due to their insulation-displacement technology method, 180°		
- 1 piece per pack		6GK1901-0DB10-6AA0
- 8 pieces per pack		6GK1901-0DB10-6AA8
PROFINET M12 connector d-coded, angled		3RK1902-2DA00

Non-assembled cables		
PROFINET FC Leitung		
- FC TP Standard Cable		6XV 1840-2AH10
- FC TP Trailing Cable		6XV 1840-3AH10
- FC TP Trailing Cable GP		6XV 1870-2D
- FC TP Marine Cable		6XV 1840-4AH10
- FC TP Torsion Cable		6XV 1870-2F
- FC TP Flexible Cable GP		6XV 1870-2B
- FC TP FRNC Cable		6XV 1871-2F
- FC TP Food Cable		6XV 1871-2L
- FC TP Festoon Cable GP		6XV 1871-2S
Pre-assembled cables		
PROFINET M12 trailable connecting cable, pre-assembled at both ends with M12 connectors, 180° (pin)	0,3 m	6XV 1870-8AE30
	5,0 m	6XV 1870-8AE50
	1,0 m	6XV 1870-8AH10
	1,5 m	6XV 1870-8AH15
	2,0 m	6XV 1870-8AH20
	3,0 m	6XV 1870-8AH30
	5,0 m	6XV 1870-8AH50
	10,0 m	6XV 1870-8AN10
PROFINET M12 trailable connecting cable, pre-assembled at both ends with M12 connectors, angled (pin)	15,0 m	6XV 1870-8AN15
	0,3 m	6XV 1870-8GE30
	5,0 m	6XV 1870-8GE50
	1,0 m	6XV 1870-8GH10
	1,5 m	6XV 1870-8GH15
	2,0 m	6XV 1870-8GH20
	3,0 m	6XV 1870-8GH30
	5,0 m	6XV 1870-8GH50
PROFINET M12 trailable connecting cable, pre-assembled at one end with M12 connector, angled (pin), other end open cable	10,0 m	6XV 1870-8GN10
	15,0 m	6XV 1870-8GN15
	3,0 m	3RK1902-2HB30
PROFINET M12 trailable connecting cable, pre-assembled at one end with M12 connector 180° (pin), other end with RJ45 Plug 145°	5,0 m	3RK1902-2HB50
	10,0 m	3RK1902-2HC10
	2,0 m	6XV 1871-5TH20
	3,0 m	6XV 1871-5TH30
	5,0 m	6XV 1871-5TH50
M12 cover caps	10,0 m	6XV 1871-5TN10
	15,0 m	6XV 1871-5TN15
		3RX9802-0AA00
M12 cover caps		3RK1901-1KA00

X03 DC 24V (7/8" pin)		
Non-assembled connectors		
7/8" plug-in connector 180° w ith socket insert		6GK1905-0FB00
7/8" plug-in connector angled w ith socket insert		3RK1902-3DA00
Non-assembled cables		
Energy Cable, trailable, 5x1,5mm ²		6XV1830-8AH10
Pre-assembled cables		
7/8" connecting cable for supplying trailable energy cable, 5x1,5mm ² , pre-assembled at both ends w ith 7/8" connectors 180° (one end socket, one end pin)	0,3 m	6XV1822-5BE30
	5,0 m	6XV1822-5BE50
	1,0 m	6XV1822-5BH10
	1,5 m	6XV1822-5BH15
	2,0 m	6XV1822-5BH20
	3,0 m	6XV1822-5BH30
	5,0 m	6XV1822-5BH50
	10,0 m	6XV1822-5BN10
	15,0 m	6XV1822-5BN15
7/8" connecting cable for supplying trailable energy cable, 5x1,5mm ² , pre-assembled at both ends w ith 7/8" connectors, angled (one end socket, one end pin)	1,5 m	6XV1822-5BH15-0SB0 ¹⁾
	2,0 m	6XV1822-5BH20-0SB0 ¹⁾
	3,0 m	3RK1902-3NB30
	5,0 m	3RK1902-3NB50
	10,0 m	3RK1902-3NC10
7/8" connecting cable for supplying trailable energy cable, 5x1,5mm ² , pre-assembled at one end w ith 7/8" connector, angled (one end socket, one end open cable)	3,0 m	3RK1902-3GB30
	5,0 m	3RK1902-3GB50
	10,0 m	3RK1902-3GC10
X04 DC 24V (7/8"-socket)		
Non-assembled connectors		
7/8" plug-in connector 180° w ith pin insert		6GK1905-0FA00
7/8" plug-in connector angled w ith pin insert		3RK1902-3BA00
Non-assembled cables		
Energy Cable, trailable, 5x1,5mm ²		6XV1830-8AH10
Pre-assembled cables		
7/8" connecting cable for supplying trailable energy cable, 5x1,5mm ² , pre-assembled at both ends w ith 7/8" connectors 180° (one end socket, one end pin)	0,3 m	6XV1822-5BE30
	5,0 m	6XV1822-5BE50
	1,0 m	6XV1822-5BH10
	1,5 m	6XV1822-5BH15
	2,0 m	6XV1822-5BH20
	3,0 m	6XV1822-5BH30
	5,0 m	6XV1822-5BH50
	10,0 m	6XV1822-5BN10
	15,0 m	6XV1822-5BN15

7/8" connecting cable for supplying trailable energy cable, 5x1,5mm ² , pre-assembled at both ends with 7/8" connectors, angled (one end socket, one end pin)	1,5 m	6XV1822-5BH15-0SB0 ¹⁾
	2,0 m	6XV1822-5BH20-0SB0 ¹⁾
	3,0 m	3RK1902-3NB30
	5,0 m	3RK1902-3NB50
	10,0 m	3RK1902-3NC10
	15,0 m	6XV1822-5BN15-0SB0 ¹⁾
7/8" cover caps		6ES7194-3JA00-0AA0

¹⁾ Ordering with ORG-ID: 10001539