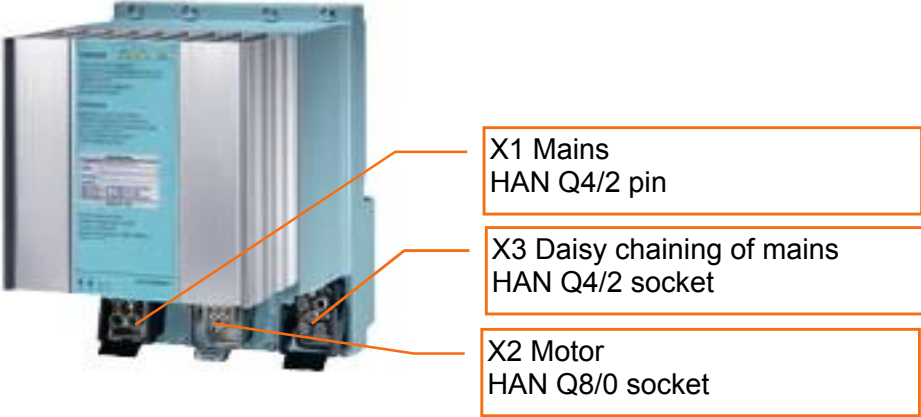


Frequency Inverter ET 200pro		
Frequency Inverter		
Frequenzumrichter ET 200pro	FC-2	6SL3514-1KE13-5AE0
Back plane module		
back plane module for ET 200pro frequency inverter		6SL3260-2TA00-0AA0
		
Interfaces		
X1 Mains supply HAN Q4/2 (pin)		
Connector set		
ISO 23570 HAN Q4/2, 1 piece per packing:	2,5 mm ²	3RK1911-2BE50
	4,0 mm ²	3RK1911-2BE10
	6,0 mm ²	3RK1911-2BE30
pre-fabricated cables		
Connection cable pre-fabricated cable at one end, open at one end, for HAN Q4/2, right angled, 4 x 4 mm ² , 1 piece per packing	1,5 m	3RK1911-0DB13
	5,0 m	3RK1911-0DB33
X2 Motor connector HAN Q8/0 (socket)		
Connector set		
Connector set ISO 23570 HAN Q8/0 for motor cable, shielded, 1 piece per packing	up to 1,5 mm ²	6ES7194-1AB01-0XA0
	up to 2,5 mm ²	ZKT: 10032011 Delivery by KnorrTec ¹ HTG: 61 88 401 0132 Delivery by Harting ²

This entry is from the Service&Support portal of Siemens AG, Sector Industry, Industry Automation and Drive Technologies. The general terms of use (http://www.siemens.com/terms_of_use) apply.

	up to 4,0 mm ²	ZKT: 10032021 Delivery by KnorrTec ¹ HTG: 61 88 401 0133 Delivery by Fa. Harting ²
pre-fabricated cables		
Motor cable for brake and temperature sensor with connector HAN Q8/0, shielded, 1 piece per packing		
– for power up to 1,5 kW	1,5 m	6ES7194-1LA01-0AA0
	3,0 m	6ES7194-1LB01-0AA0
	5,0 m	6ES7194-1LC01-0AA0
	10,0 m	6ES7194-1LD01-0AA0
– 1,0 mm ²	1,5 m	ZKT: 70018601000150 Delivery by KnorrTec ¹
	3,0 m	ZKT: 70018601000300 Delivery by KnorrTec ¹
	5,0 m	ZKT: 70018601000500 Delivery by KnorrTec ¹
	10,0 m	ZKT: 70018601001000 Delivery by KnorrTec ¹
– 1,5 mm ²	1,5 m	HTG: 61 88 201 0288 Delivery by Harting ²
	3,0 m	HTG: 61 88 201 0289 Delivery by Harting ²
	5,0 m	HTG: 61 88 201 0290 Delivery by Harting ²
	10,0 m	HTG: 61 88 201 0299 Delivery by Harting ²

- 2,5 mm ²	1,5 m	ZKT: 70009601000150 Delivery by KnorrTec ¹ HTG: 61 88 201 0291 Delivery by Harting ²
	3,0 m	ZKT: 70009601000300 Delivery by KnorrTec ¹ HTG: 61 88 201 0292 Delivery by Harting ²
	5,0 m	ZKT: 70009601000500 Delivery by KnorrTec ¹ HTG: 61 88 201 0293 Delivery by Harting ²
	10,0 m	ZKT: 70009601001000 Delivery by KnorrTec ¹ HTG: 61 88 201 0301 Delivery by Harting ²
- 4,0 mm ²	1,5 m	ZKT: 70017001000150 Delivery by KnorrTec ¹ HTG: 61 88 201 0303 Delivery by Harting ²
	3,0 m	ZKT: 70017001000300 Delivery by KnorrTec ¹ HTG: 61 88 201 0304 Delivery by Harting ²
	5,0 m	ZKT: 70017001000500 Delivery by KnorrTec ¹ HTG: 61 88 201 0305 Delivery by Harting ²
	10,0 m	ZKT: 70017001001000 Delivery by KnorrTec ¹ HTG: 61 88 201 0306 Delivery by Harting ²

X3 Daisy chaining of energy HAN Q4/2 (socket)		
pre-fabricated connectors		
Power jumper plug for power transmission (400V), 1 piece per packing		3RK19 22-2BQ00
Connector set (all parts of the connector are Harting Q4/2)		
Housing		0912 006 3141
Crimp, pin 4 mm ² / AWG 12		0932 000 6107
Screwing/ sealing		0900 000 5059
Cap		0912 008 5407
Crimping tool (Q8/0 and Q4/2) (Harting order numbers¹)		
Crimping tool (Q8/0 and Q4/2)		0999 000 0001
Einsätze für Crimpwerkzeug	0,5 mm ² (AWG 20)	0999 000 0007
	1,5 mm ² (AWG 16)	0999 000 0007
	4 mm ² (AWG 12)	0999 000 0006
	6 mm ² (AWG 10)	without insert
Tool for disassembling (Q8/0)		0999 000 0319
Tool for disassembling (Q4/2)		0999 000 0305
Blank plug for 9-pole power sockets		
Blank plug for 9-pole power sockets to meet IP65 rating (without blank plug IP rating only IP54)		
- 1 piece per packing		3RK1902-0CK00
- 10 pieces per packing		3RK1902-0CJ00
Optical interface		
Optical cable for connecting an engineering device or a control device to the RS232 interface of ET 200pro FC		
RS232 interface cable		3RK1922-2BP00
USB interface cable		6SL3555-0PA00-2AA0
Multi Media Card (MMC)		
Multi Media Card for storage of parameter from a control unit		
Multi Media Card (MMC)		6SL3254-0AM00-0AA0

1) Components by Siemens Solution Partner Knorrtec

2) Components by Siemens Solution PartnerHarting

[Siemens Solution Partner - KnorrTec Ergänzungsprodukte](#)

[Siemens Solution Partner - Harting Ergänzungsprodukte](#)

This entry is from the Service&Support portal of Siemens AG,
Sector Industry, Industry Automation and Drive Technologies.