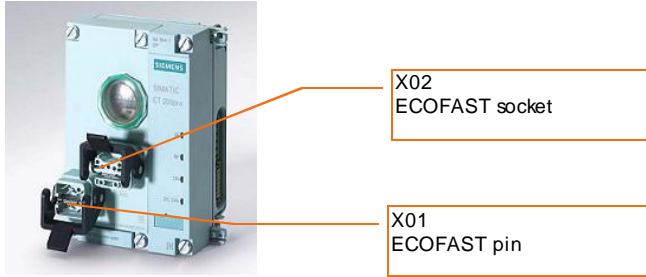
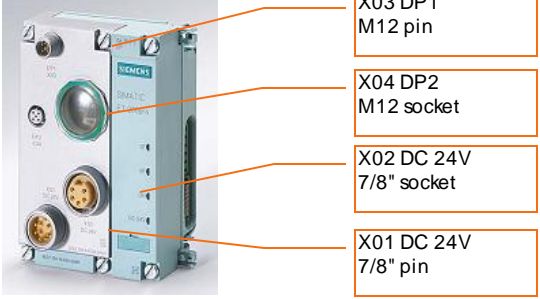
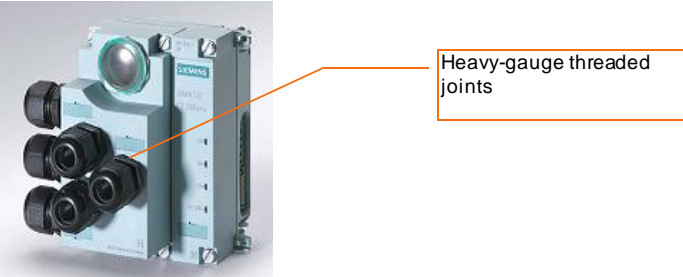
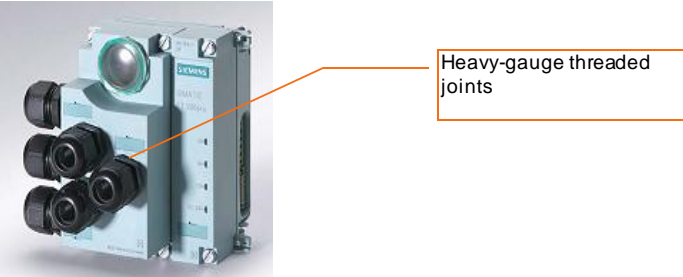


Interface modules PROFIBUS			
Interface modules		Article number	
IM154-1 DP		6ES7154-1AA01-0AB0	
IM154-2 DP HF		6ES7154-2AA01-0AB0	
Connection module		Article number	
CM IM DP ECOFAST Cu		6ES7194-4AA00-0AA0	
			
			
Connection module		Article number	
CM IM DP M12, 7/8"		6ES7194-4AD00-0AA0	
			
Connection modul		Article number	
CM IM DP Direkt		6ES7194-4AC00-0AA0	
Interfaces		Article number	
X01 ECOFAST (pin)			
non-assembled connectors			
PROFIBUS ECOFAST Hybrid Plug 180° with socket insert		6GK1905-0CB00	
PROFIBUS ECOFAST Hybrid Plug angled with socket insert		6GK1905-0CD00	
non-assembled cables			
PROFIBUS ECOFAST Hybrid Cable, trailing cable (PUR sheath)	20m	6XV1830-7AN20	
	50m	6XV1830-7AN50	
	100m	6XV1830-7AT10	
PROFIBUS ECOFAST Hybrid Cable, trailing cable (PUR sheath); sold by the meter		6XV1830-7AH10	
PROFIBUS ECOFAST Hybrid Cable GP, trailing cable (PVC sheath); sold by the meter		6XV1860-2P	
PROFIBUS ECOFAST Hybrid Cable GP, trailing cable (PVC sheath)	20m	6XV1860-4PN20	
	50m	6XV1860-4PN50	
	100m	6XV1860-4PT10	
pre-assembled cables			
PROFIBUS ECOFAST Hybrid Cable, trailing cable (PUR sheath), pre-assembled at both ends with ECOFAST Hybrid Plug 180° (one end socket, one end pin)	0,5 m	6XV1830-7BH05	
	1,0 m	6XV1830-7BH10	
	1,5 m	6XV1830-7BH15	
	3,0 m	6XV1830-7BH30	
	5,0 m	6XV1830-7BH50	
	10,0 m	6XV1830-7BN10	
	15,0 m	6XV1830-7BN15	
	20,0 m	6XV1830-7BN20	
	25,0 m	6XV1830-7BN25	
	30,0 m	6XV1830-7BN30	
	35,0 m	6XV1830-7BN35	
	40,0 m	6XV1830-7BN40	
	45,0 m	6XV1830-7BN45	
	50,0 m	6XV1830-7BN50	
PROFIBUS ECOFAST Hybrid Cable GP, trailing cable (PVC sheath), pre-assembled at both ends with ECOFAST Hybrid Plug 180° (one end socket, one end pin)	0,5 m	6XV1860-3PH05	
	1,0 m	6XV1860-3PH10	
	1,5 m	6XV1860-3PH15	
	3,0 m	6XV1860-3PH30	
	5,0 m	6XV1860-3PH50	
	10,0 m	6XV1860-3PN10	
	15,0 m	6XV1860-3PN15	
	20,0 m	6XV1860-3PN20	
	25,0 m	6XV1860-3PN25	
	30,0 m	6XV1860-3PN30	
	35,0 m	6XV1860-3PN35	
	40,0 m	6XV1860-3PN40	
	45,0 m	6XV1860-3PN45	
	50,0 m	6XV1860-3PN50	
X02 ECOFAST (socket)			
non-assembled connectors			
PROFIBUS ECOFAST Hybrid Plug 180° with pin insert		6GK1905-0CA00	
PROFIBUS ECOFAST Hybrid Plug angled with pin insert		6GK1905-0CC00	
Interfaces			
X01 DC 24V 7/8" (pin)			
non-assembled connectors			
7/8" plug-in connector 180° with socket insert		6GK1905-0FB00	
7/8" plug-in connector angled with socket insert		3RK1902-3DA00	
non-assembled cables			
Energy Cable, trailable, 5 x 1,5 mm²		6XV1830-8AH10	
pre-assembled cables			
7/8" connecting cable for supplying trailable energy cable, 5 x 1,5 mm², pre-assembled at both ends with 7/8" connectors 180° (one end socket, one end pin)	0,3m	6XV1822-5BE30	
	0,5m	6XV1822-5BE50	
	1,0m	6XV1822-5BH10	
	1,5 m	6XV1822-5BH15	
	2,0 m	6XV1822-5BH20	
	3,0 m	6XV1822-5BH30	
	5,0 m	6XV1822-5BH50	
	10,0 m	6XV1822-5BN10	
	15,0 m	6XV1822-5BN15	
7/8" connecting cable for supplying trailable energy cable, 5 x 1,5 mm², pre-assembled at both ends with 7/8" connectors angled (one end socket, one end pin)	1,5 m	6XV1822-5BH15-0SB0 ¹⁾	
	2,0 m	6XV1822-5BH20-0SB0 ¹⁾	
	3,0 m	3RK1902-3NB30	
	5,0 m	3RK1902-3NB50	
	10,0 m	3RK1902-3NC10	
	15,0 m	6XV1822-5BN15-0SB0 ¹⁾	
7/8" connecting cable for supplying trailable energy cable, 5 x 1,5 mm², one end with 7/8" connector angled (one end socket, one end open cable)	3,0 m	3RK1902-3GB30	
	5,0 m	3RK1902-3GB50	
	10,0 m	3RK1902-3GC10	
X02 DC 24V 7/8" (socket)			
non-assembled connectors			
7/8" connector 180° with pin insert		6GK1905-0FA00	
7/8" connector angled with pin insert		3RK1902-3BA00	
non-assembled cables			
Energy Cable, trailable, 5 x 1,5 mm²		6XV1830-8AH10	
pre-assembled cables			
7/8" connecting cable for supplying trailable energy cable, 5 x 1,5 mm², pre-assembled at both ends with 7/8" connectors 180° (one end socket, one end pin)	0,3m	6XV1822-5BE30	
	0,5m	6XV1822-5BE50	
	1,0m	6XV1822-5BH10	
	1,5 m	6XV1822-5BH15	
	2,0 m	6XV1822-5BH20	
	3,0 m	6XV1822-5BH30	
	5,0 m	6XV1822-5BH50	
	10,0 m	6XV1822-5BN10	
	15,0 m	6XV1822-5BN15	
7/8" connecting cable for supplying trailable energy cable, 5 x 1,5 mm², pre-assembled at both ends with 7/8" connectors angled (one end socket, one end pin)	1,5 m	6XV1822-5BH15-0SB0 ¹⁾	
	2,0 m	6XV1822-5BH20-0SB0 ¹⁾	
	3,0 m	3RK1902-3NB30	
	5,0 m	3RK1902-3NB50	
	10,0 m	3RK1902-3NC10	

non-assembled cables				15,0 m	6XV1822-5BN15-0SB0 ¹⁾		
PROFIBUS ECOFAST Hybrid Cable, trailing cable (PUR sheath)	20m	6XV1830-7AN20	7/8" cover caps		6ES7194-3JA00-0AA0		
	50m	6XV1830-7AN50	X03 DP1 M12 (pin)				
	100m	6XV1830-7AT10	non-assembled connectors				
PROFIBUS ECOFAST Hybrid Cable, trailing cable (PUR sheath); sold by the meter		6XV1830-7AH10	PROFIBUS M12 connector 180° with socket insert		6GK1 905-0EB00		
PROFIBUS ECOFAST Hybrid Cable GP, trailing cable (PVC sheath); sold by the meter		6XV1 860-2P	PROFIBUS M12 connector fast connect 180° with socket insert		6GK1 905-0EB10		
PROFIBUS ECOFAST Hybrid Cable GP, trailing cable (PVC sheath)	20m	6XV1860-4PN20	PROFIBUS M12 connector angled with socket insert		3RK1902-1DA00		
	50m	6XV1860-4PN50	non-assembled cables				
	100m	6XV1860-4PT10	PROFIBUS FC cable				
pre-assembled cables			- FC Standard Cable		6XV1830-0EH10		
PROFIBUS ECOFAST Hybrid Cable, trailing cable (PUR sheath); pre-assembled at both ends with ECOFAST Hybrid Plug 180° (one end socket, one end pin)	0,5 m	6XV1830-7BH05	- FC Trailing Cable		6XV1830-3EH10		
	1,0 m	6XV1830-7BH10	- FC Food Cable (PE sheath)		6XV1830-0GH10		
	1,5 m	6XV1830-7BH15	- FC Robust Cable (PUR sheath)		6XV1830-0JH10		
	3,0 m	6XV1830-7BH30	- FC FRNC Cable (FRNC sheath)		6XV1830-0LH10		
	5,0 m	6XV1830-7BH50	- FC Underground Cable		6XV1830-3FH10		
	10,0 m	6XV1830-7BN10	- Festoon Cable GP (PVC sheath)		6XV1830-3GH10		
	15,0 m	6XV1830-7BN15	- FC Flexible Cable GP (PUR sheath)		6XV1831-2K		
	20,0 m	6XV1830-7BN20	pre-assembled cables				
	25,0 m	6XV1830-7BN25	PROFIBUS M12 connecting cable, trailable,	0,3m	6XV1830-3DE30		
	30,0 m	6XV1830-7BN30	pre-assembled at both ends with PROFIBUS M12 connectors	0,5m	6XV1830-3DE50		
	35,0 m	6XV1830-7BN35	180°	1,0m	6XV1830-3DH10		
	40,0 m	6XV1830-7BN40	(one end socket, one end pin)	1,5 m	6XV1830-3DH15		
	45,0 m	6XV1830-7BN45		2,0 m	6XV1830-3DH20		
50,0 m	6XV1830-7BN50		3,0 m	6XV1830-3DH30			
PROFIBUS ECOFAST Hybrid Cable GP, trailing cable (PVC sheath), pre-assembled at both ends with ECOFAST Hybrid Plug 180° (one end socket, one end pin)	0,5 m	6XV1860-3PH05		5,0 m	6XV1830-3DH50		
	1,0 m	6XV1860-3PH10		10,0 m	6XV1830-3DN10		
	1,5 m	6XV1860-3PH15		15,0 m	6XV1830-3DN15		
	3,0 m	6XV1860-3PH30	PROFIBUS M12 connecting cable, trailable,	1,5 m	6XV1830-3DH15-0SB0 ¹⁾		
	5,0 m	6XV1860-3PH50	pre-assembled at both ends with PROFIBUS M12 connectors	2,0 m	6XV1830-3DH20-0SB0 ¹⁾		
	10,0 m	6XV1860-3PN10	angled (one end socket, one end pin)	3,0 m	3RK1902-1NB30		
	15,0 m	6XV1860-3PN15		5,0 m	3RK1902-1NB50		
	20,0 m	6XV1860-3PN20		10,0 m	3RK1902-1NC10		
	25,0 m	6XV1860-3PN25		15,0 m	6XV1830-3DN15-0SB0 ¹⁾		
	30,0 m	6XV1860-3PN30	X04 DP2 M12 (socket)				
35,0 m	6XV1860-3PN35	non-assembled connectors					
40,0 m	6XV1860-3PN40	PROFIBUS M12 connector 180° with pin insert		6GK1905-0EA00			
45,0 m	6XV1860-3PN45	PROFIBUS M12 connector fast connect 180° with pin insert		6GK1905-0EA10			
50,0 m	6XV1860-3PN50	PROFIBUS M12 connector angled with pin insert		3RK1902-1BA00			
ECOFAST cover caps		6ES7194-1JB10-0XA0	non-assembled cables				
			PROFIBUS FC cable				
			- FC Standard Cable		6XV1830-0EH10		
			- FC Trailing Cable		6XV1830-3EH10		
			- FC Food Cable (PE sheath)		6XV1830-0GH10		
			- FC Robust Cable (PUR sheath)		6XV1830-0JH10		
			- FC FRNC Cable (FRNC sheath)		6XV1830-0LH10		
			- FC Underground Cable		6XV1830-3FH10		
			- Festoon Cable GP (PVC sheath)		6XV1830-3GH10		
			- FC Flexible Cable GP (PUR sheath)		6XV1831-2K		
			pre-assembled cables				
			PROFIBUS M12 connecting cable, trailable,	0,3m	6XV1830-3DE30		
			pre-assembled at both ends with PROFIBUS M12 connectors	0,5m	6XV1830-3DE50		
			180°	1,0m	6XV1830-3DH10		
			(one end socket, one end pin)	1,5 m	6XV1830-3DH15		
				2,0 m	6XV1830-3DH20		
				3,0 m	6XV1830-3DH30		
				5,0 m	6XV1830-3DH50		
				10,0 m	6XV1830-3DN10		
				15,0 m	6XV1830-3DN15		

			PROFIBUS M12 connecting cable, trailable,	1,5 m	6XV1830-3DH15-0SB0 ¹⁾		
			pre-assembled at both ends with PROFIBUS M12 connectors	2,0 m	6XV1830-3DH20-0SB0 ¹⁾		
			angled (one end socket, one end pin)	3,0 m	3RK1902-1NB30		
				5,0 m	3RK1902-1NB50		
				10,0 m	3RK1902-1NC10		
				15,0 m	6XV1830-3DN15-0SB0 ¹⁾		
			PROFIBUS M12 connecting cable, trailable,	3,0 m	3RK1902-1GB30		
			pre-assembled at one end with PROFIBUS M12 connector angled	5,0 m	3RK1902-1GB50		
			(one end pin, one end open cable)	10,0 m	3RK1902-1GC10		
			M12 cover caps		3RX9802-0AA00		
			M12 cover caps		3RK1901-1KA00		
			M12 terminating resistor for PROFIBUS DP	5 pieces	6GK1905-0EC00		

¹⁾ Ordering with ORG-ID: 10001539