


Catalog Numbers

Catalog No.	Amperage Rating	Max. Interrupting Rating
1 PHASE, 3 WIRE, 120/240V AC MAX		
WBV1200C	200	85,000
WBV1200CU	200	100,000
WBV1250C	250	85,000
WBV1250CU	250	100,000
WBV1300C	300	85,000
WBV1300CU	300	100,000
WBV1350C	350	85,000
WBV1350CU	350	100,000
WBV1400C	400	85,000
WBV1400CU	400	100,000


- TYPE 3R OUTDOOR ENCLOSURE
- MAIN BUS RATING: 1200A MAX., 240V AC Max.
- 1 PHASE
- FOR OVERHEAD OR UNDERGROUND SERVICE
- 3VA BREAKER TECHNOLOGY
- MOUNTING RAILS AND ADJUSTABLE BRACKETS FOR SECURE MOUNTING

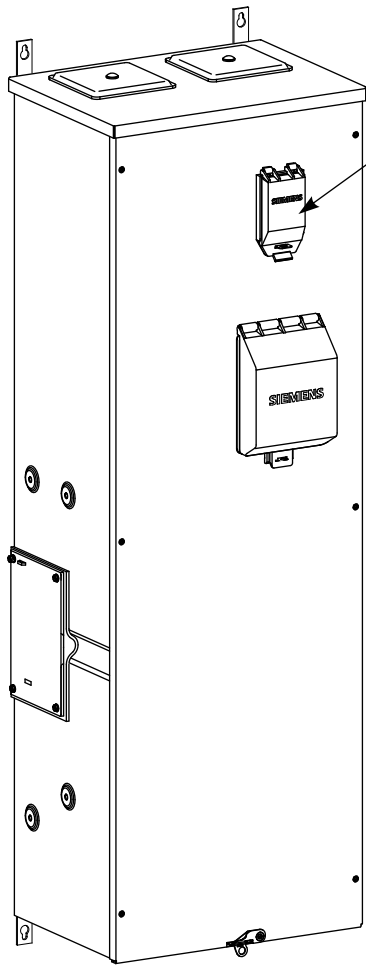


CLEAR COVER FOR USE WHEN BSPD SURGE PROTECTION KIT IS INSTALLED (SEE ACCY CHART)

(2) #4-300 kcmil GROUND LUGS


View Shown Without Door and LTB Shield

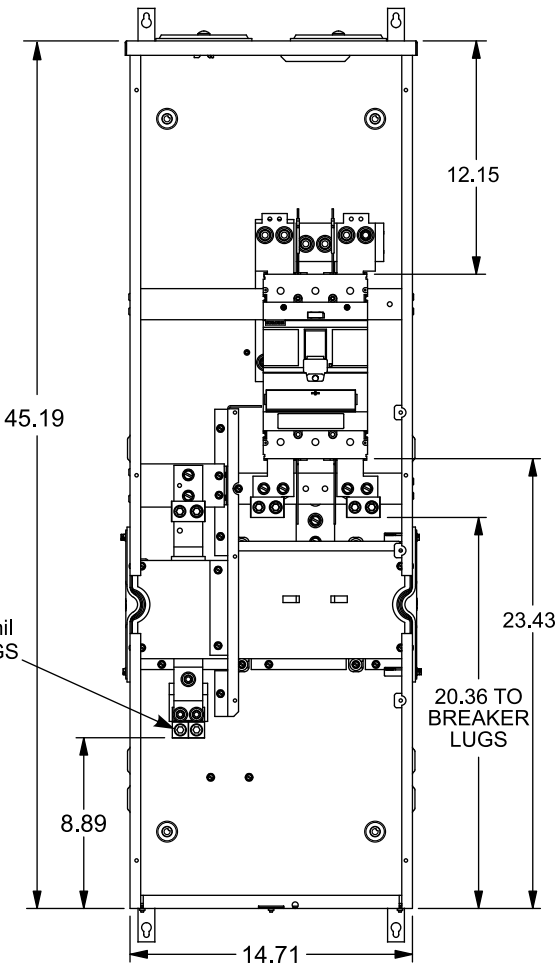

REMOVABLE BOTTOM ENDWALL OPENING

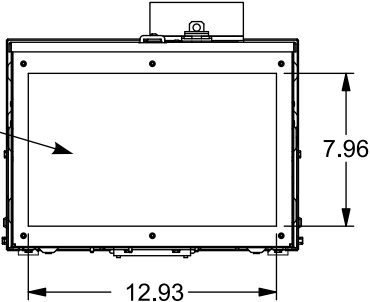

(2) TYPE "HD" HUB OPENINGS - 4" MAX FACTORY INSTALLED COVER PLATES

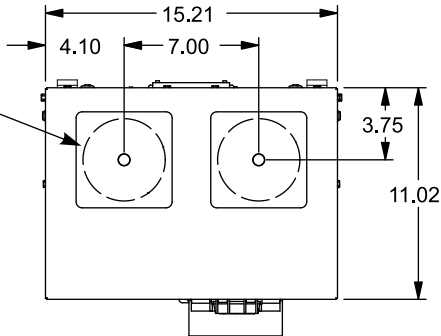

Replacement Parts, Accessories, and Additional Modules


For use with:	Series#
Main Breakers	WB(M), WEB(M), WBV, WXB(M), BFT(M)
Switches	WMP, WS, WES, WXS
Tap/Terminal Boxes	WTB, WET, WT_PU, WTBN, WBT(M)
Pull Boxes	WMMB
Meter Module	(W)MM, (W)MT, (W)ML, (W)MK, (W)MLZ(F), (W)MN
Meter Combinations	WC, WCL, WCT
Extension Box	WSP, WSPD, SPT
Bussed Elbow	BE, WELB, ELBT

Accessories	Catalog Number
Hub Cover Plate	EC56933S
Type HD Hub 3"	EC56856
Type HD Hub 3-1/2"	EC56857
Type HD Hub 4"	EC56858
GND Bar Kit	ECLX069M
Ground Lug Kit (3 Pos.)	ECGLK3300, (3) #6-300kcmil
Ground Lug Kit (6 Pos.)	ECGLK6300, (6) #6-300kcmil
Surge Protection Mtg Kit	ECBSPDV3 (BSPD sold separately)
Lug Landing Pad	LLPV600 (lugs ordered separately) UNDERGROUND USE ONLY

Breaker Lug Kits (kits include 3 lugs)				
Lug Kit	MFG	Wire Range	No. Wires per phase	Torque (lb.-in.)
LK12500 (factory installed)	Siemens	3/0-500 kcmil CU	2	300
LK11750	Siemens	500-750 kcmil	1	500


Connect Modules	
Using:	Catalog Number / Torque
QuickConnect	QC1, Torque 400-440 lb-in (35-36 ft.-lb.)

Schematic

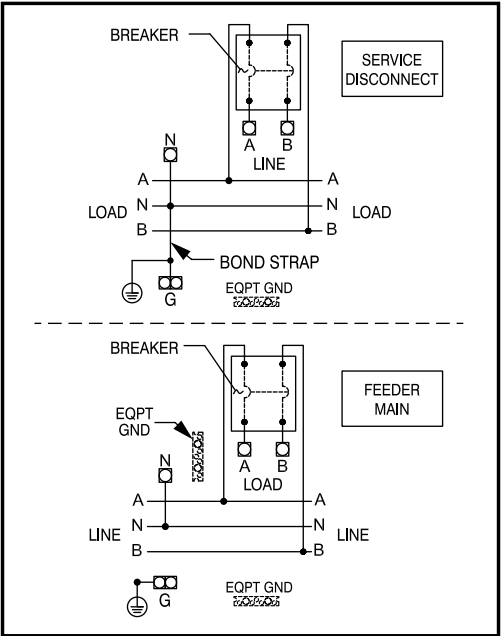

LLPV600 Lug Landing Kit

VIEW WITH LUG LANDING KIT INSTALLED SHOWN WITHOUT LUGS INSTALLED

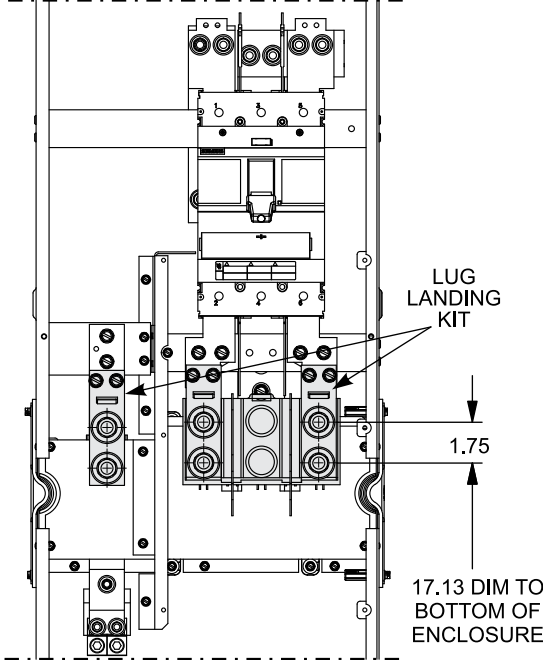

Lug Kits for LLPV600 Phase and Neutral Connections

NEMA Lug	MFG	Wire Range	Type	No. Wires per phase	Torque (lb.-in.)
LK11600N2	Siemens	#2-600 kcmil	Mechanical	1	500
LK12350N2	Siemens	#6-350 kcmil	Mechanical	2	275
2ACL-600	ILSCO	600 kcmil	Compression	1	NA
2ACL-350	ILSCO	350 kcmil	Compression	2	NA

© 2022 Copyright Siemens Industry, Inc.

SIEMENS
Siemens Industry, Inc.

PowerMod™ Breaker Mains

Description: **WBV 200-400A, OH/UG
1 Phase Breaker Mains (3VA)**

KAM 9/28/22 DO NOT SCALE DRAWING Dwg No: **WBV1200C-WBV1400CU**