

Catalog Number: UA2736-ZGF


Features and Ratings

- Ringless Type Meter Socket
- Aluminum Enclosure
- 200A Continuous, 250A Max, 2 Position, 200Amp Overall
- Outdoor Enclosure (NEMA Type 3R)
- 1 Phase, 3 Wire, 600V AC
- 4 Jaw
- For Overhead or Underground Service
- HD Hub Opening With Coverplate Installed





CONNECTORS	WIRE SIZE	TORQUE
LINE*	#6-350MCM	250 IN-LB
LOAD*	#6-350MCM	250 IN-LB
GROUND	#14-2	50 IN-LB

* External Hex drive 1/2"
* Internal Hex drive 5/16"

ACCESSORIES	HD HUB KITS	5th Terminal Use Talon Kit
HD Cover Plate Cat No: H56933-4	Cat No: H56856-2 (3.00") Cat No: H56857-2 (3.50") Cat No: H56858-2 (4.00")	Cat No: 659-0121
HD Cover Plate Cat No: EC56933S	HD HUB KITS Cat No: EC56856 (3.00") Cat No: EC56857 (3.50") Cat No: EC56858 (4.00")	

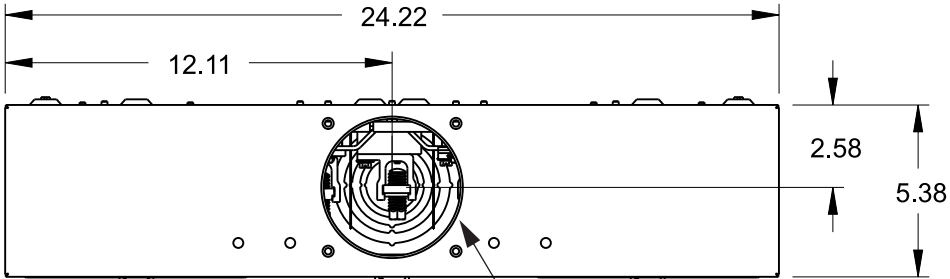

HD HUB PROVISION
Factory Installed (Not Shown)

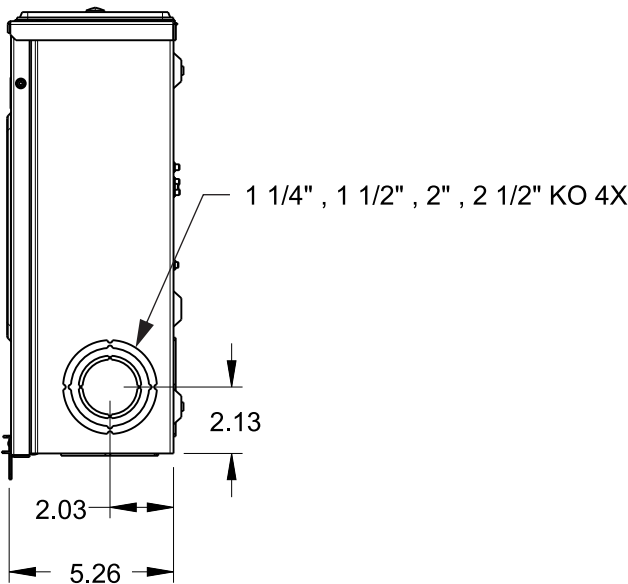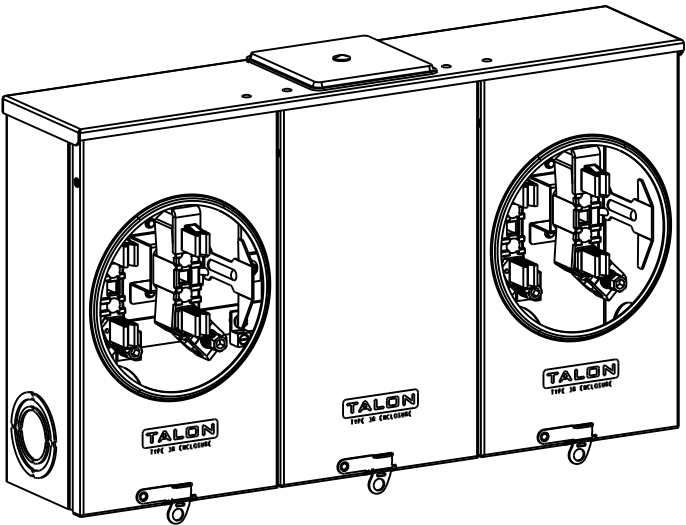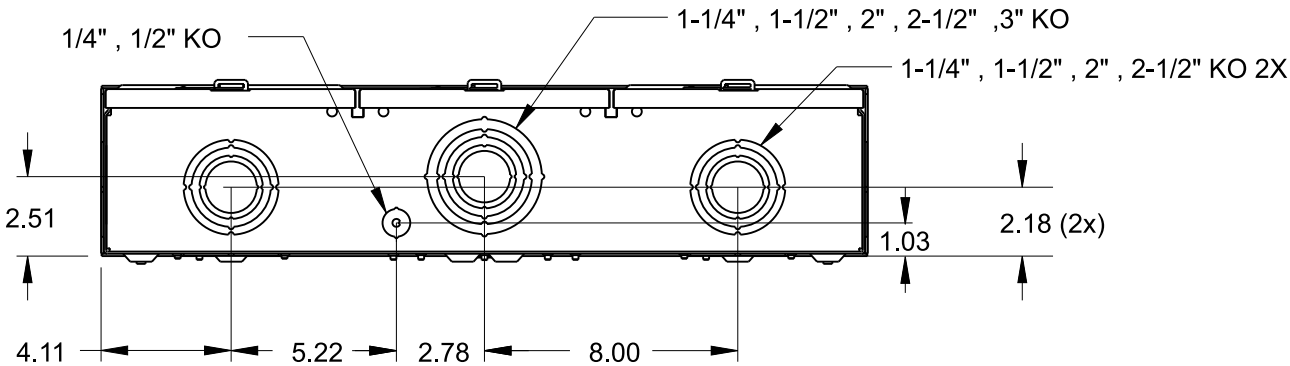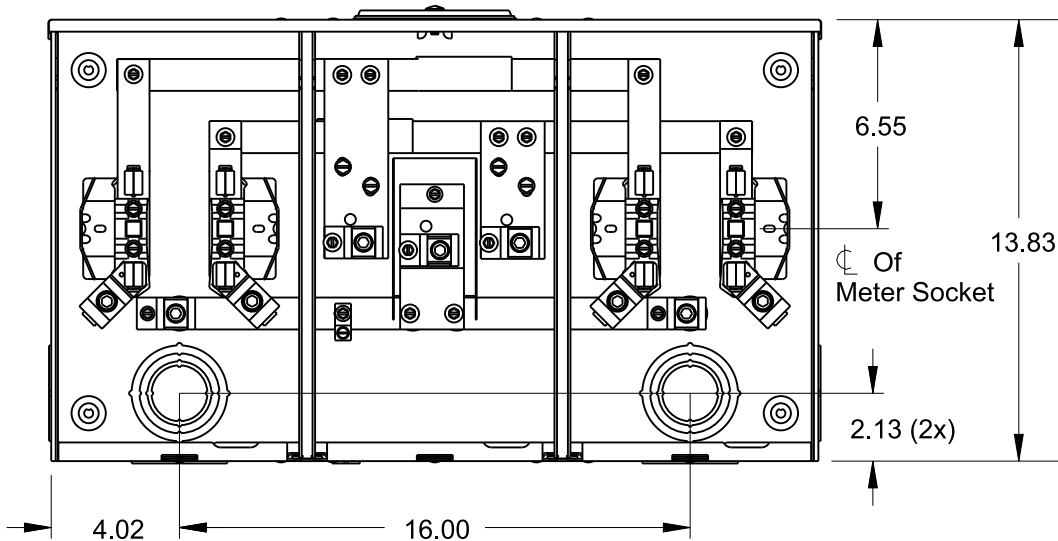

TALON

Multi-Position Metering

Description:
200A Cont, 4 Jaw, A14, 600V AC,
Aluminum Enclosure

MEG

NH 26NOV15

DO NOT SCALE DRAWING

Dwg No: UA2736-ZGF