

VIEW SHOWN
WITHOUT COVER

(6) #4-2/0
NEUTRAL LUGS

REMOVABLE BACK PLATE
WITH (6) 1, 1-1/4, 1-1/2, 2" KOs

(7) #4-2/0
GROUND LUGS

SPRING LOADED
STUDS - SEE DETAIL

70-5/16

9
TYP.

12-5/32

4" TYP. TO METER
SOCKET CENTER

12-31/32

36" TO
BOTTOM OF
QUICK ROLL
BRACKET

24-3/8 TO
CROSS BUS
CENTER

TOP VIEW

(6) CENTER PUNCH
LOCATORS

WMM61125RB
SHOWN

ENLARGED SOCKET DETAIL


HORN BYPASS

BARREL LOCK
PROVISIONS

Accessories

Description	Catalog No.
Horn By-Pass Mod	ECMFH
End Closure Plate	WMEP
5th Jaw Mod	ECMF5
Meter Cover Plate	ECCP3
Meter Socket	ECMFS
125A Breaker Mounting	ECMFBM1
Meter Cover, Ring Type	ECMFMC
Meter Cover, Ringless	ECMFMCR
Parts Kit	ECMFPK
Load Cover Screws	ECMFCS
Bottom Pull Cover	ECMFC
Mounting Rail	MMRAIL
Mounting Clip	MMCLIP
Quick Phase Strap	ECMFPS
Breaker Cover Repl.	ECBC
Mounting Tabs (2)	ECMFTAB
Ground/Nil Bar Kit	ECMFGN125
Ringless Conversion Kit	ECMMLCK
Back Rail/Clip	ECMFWLCLIP
Wall Mounting Rail (60")	MMZR60
QP Breaker Retainer	ECMBR2
KO Plate with Knockouts	ECMMKOP
KO Plate w/o Knockouts	ECMMNKOP
4/0 QP Lug Adapter	WM40LA

Schematic

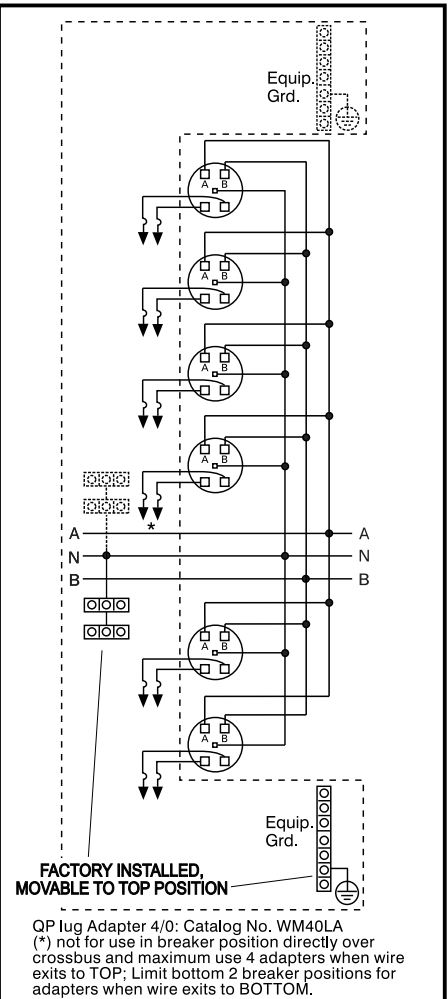

SIEMENS
Siemens Industry, Inc.

PowerMod™ Meter Stack

Description: WMM61125, WMM61125R, WMM61125RB,
WMM61125J, WMM61125RJ, WMM61125RJB

KAM
11/14/22

DO NOT
SCALE DRAWING

Dwg.
No.

125A_1Ph_6Pos

Catalog Numbers, Features and Ratings

- MAIN BUS RATING: 1200 AMPS 240V AC MAX.
- METER SOCKET RATING: 125 AMPS CONTINUOUS
- 65,000 AIC RATING MAX., 125 AMPS MAX. BRANCH RATING
- 1 PHASE INPUT / 1 PHASE OUTPUT
- TYPE 3R OUTDOOR ENCLOSURE
- MOUNTING RAILS AND ADJUSTABLE BRACKETS FOR SECURE MOUNTING
- CATALOG No. WITH RING TYPE COVER COMPLIES WITH EUSERC DWG No. 353

Catalog No.	Main Bus	Branch Rating	Meter Positions	Cover Type	Cover 5th Jaw	Horn Bypass
WMM61125	1 Phase	125A Max.	6	Ring		
WMM61125R	1 Phase	125A Max.	6	Ringless		
WMM61125RB	1 Phase	125A Max.	6	Ringless		Installed
WMM61125J	1 Phase	125A Max.	6	Ring	Installed	
WMM61125RJ	1 Phase	125A Max.	6	Ringless	Installed	
WMM61125RJB	1 Phase	125A Max.	6	Ringless	Installed	Installed

Additional Modules

For use with:

Module Description	Series#
Main Breakers	WB(M), WEB(M), WBV, WXB(M), BFT(M)
Switches	WMP, WS, WES, WXS
Tap/Terminal Boxes	WTB, WET, WT_PU, WTBN, WBT(M)
Pull Boxes	WMMB
Meter Module	(W)MM, (W)MT, (W)ML, (W)MK, (W)MLZ(F), (W)MN
Meter Combinations	WC, WCL, WCT,
Extension Box	WSP, WSPD, SPT
Bussed Elbow	BE, WELB, ELBT

Connect Modules Using:	Catalog Number / Torque
QuickConnect	QC1, Torque 400-440 lb-in (35-36 ft.-lb.)